

Fixings and PCB Mounts

Order code	Manufacturer code	Description
33-3576	R30-3001002	PACK 25 10MM M-F HEX SPACER RC

Fixings and PCB Mounts

Page 1 of 2

The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.

Revision A
20/02/2007


Spacers

Brass Hexagonal Pillars


- ❖ Special body lengths can be specified, by modifying the order code. For example, R30-400xx02, xx denotes body length in mm.
- ❖ Please contact technical@harwin.com for further information.
- ❖ Base material is free-machining brass, with nickel plating.



MALE/MALE

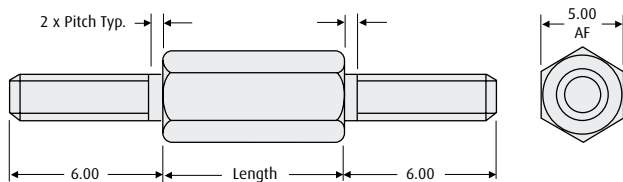

MALE/FEMALE

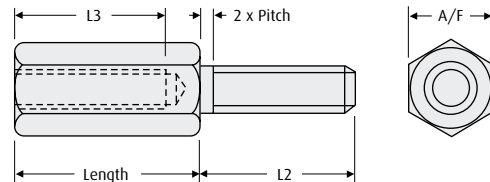

CALCULATION OF L3 (min)

Series	Length mm										
	4	5	6	7	8	9	10	11	12	13	14+
R30-300	2.5	3.0	3.0	5.0	5.5	6.0	6.0	6.0	6.0	6.0	6.0
R30-301	2.5	3.0	3.0	5.0	5.5	6.0	7.0	8.0	8.0	8.0	8.0
R40-300	x	x	2.5	3.0	4.5	5.5	6.5	8.0	8.0	8.0	8.0
R50-300	x	x	x	x	4.0	5.0	6.0	7.5	8.0	10.0	10.0
R60-300	x	x	x	x	x	x	5.0	7.0	7.0	8.0	10.0

HOW TO ORDER

R XX - XXX XX 02

SERIES CODE

THREAD SIZE & STYLE

R30-300	M3 Male/Female, 5.0mm A/F, L2 = 6mm
R30-301	M3 Male/Female, 5.0mm A/F, L2 = 8mm
R30-400	M3 Male/Male
R40-300	M4 Male/Female, 7.0mm A/F, L2 = 8mm
R50-300	M5 Male/Female, 8.0mm A/F, L2 = 10mm
R60-300	M6 Male/Female, 10.0mm A/F, L2 = 10mm

FINISH

02 Nickel

LENGTH (mm)

04-16, 18, 20, 25, 30, 35, 40	R30
06-16, 18, 20, 25, 30, 35	R40
08-16, 18, 20, 25, 30, 35, 40	R50
10-16, 18, 20, 25, 30, 40	R60

All dimensions in mm.

www.harwin.com

