

## BNC connectors

Order code	Manufacturer code	Description
85-0290	HT-336A	BNC RATCHET CRIMPING PLIERS (RE)

BNC connectors	Page 1 of 3
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

# Professional Crimping Tool Ratchet Type

- Die sets are interchangeable, except HT-301
- OEM/Custom designs are welcome



HT-336FM  
(Frame only)  
8.7" (220mm)

Item No	HT-5133A/HT-336A	HT-5133A4/HT-336A4	HT-5133C/HT-336C
Die P/N	3A	3A4	3C
Specifications	.256"/.068"/.213" 6.50/1.73/5.41mm	.255"/.187"/.068"/.213" 6.48/4.75/1.73/5.41mm	.256"/.319"/.068"/.213" 6.50/8.10/1.73/5.41mm
Crimping cable size	RG58,59,62	RG58,59,62,174	RG58,59,62,6

 
Item No	HT-5133C1/HT-336C1	HT-5133C2/HT-336C2	HT-5133D/HT-336D
Die P/N	3C1	3C2	3D
Specifications	.068"/.216"/.324"/.360" 1.73/5.49/8.23/9.14mm	.068"/.262"/.324"/.360" 1.73/6.65/8.23/9.14mm	.213"/.256"/.068"/.324" 5.41/6.50/1.73/8.23mm
Crimping cable size	RG58,59,62,6	CATV" F" Connectors RG59,6	RG58,59,62,6

# HT-336A RATCHET CRIMPING TOOL

## SPECIFICATION:

\* **Item No** HT-336A

\* **Crimping Range**

	.256" 6.50mm	.068" 1.72mm	.213" 5.41mm
Description	For Crimping RG 58,59,62 Cable		

\* **Length** 8.7"(220mm)

\* **Weight** 500g


\* **Material**

Frame –Made Of 2.8mm Middle Carbon Steel .  
Crimper- Made Of Off Wax.

\* **Finished**

Black Oxide Finished With Hardened

Crimper

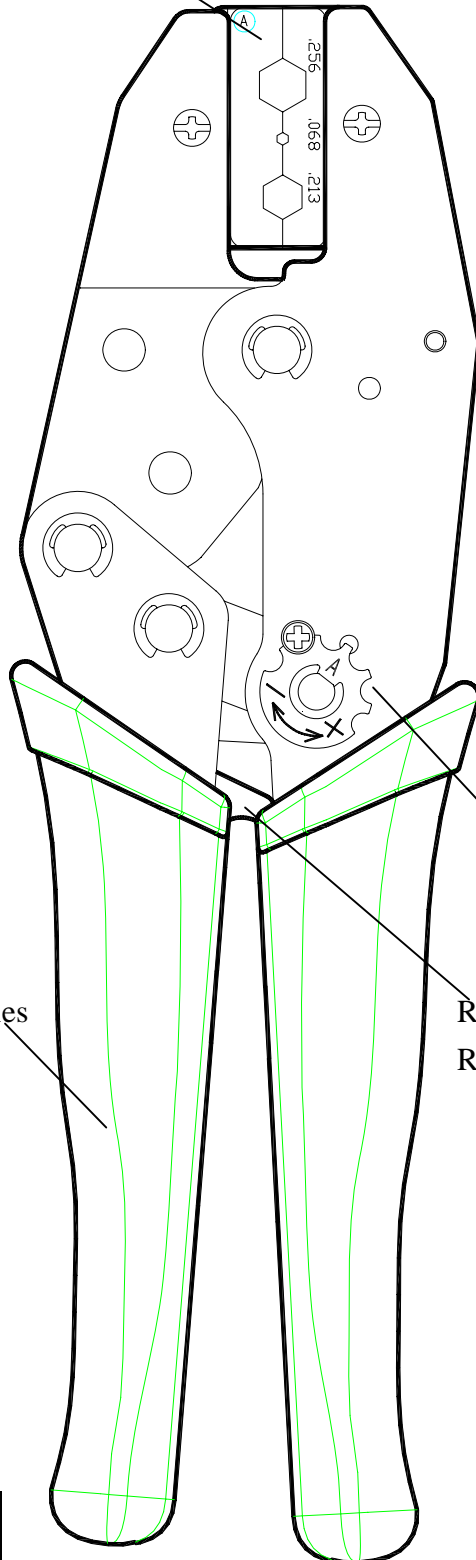

With  
Adjusting Disc

Ratchet  
Release

PP Handles