


PICTURE

DIMENSIONS

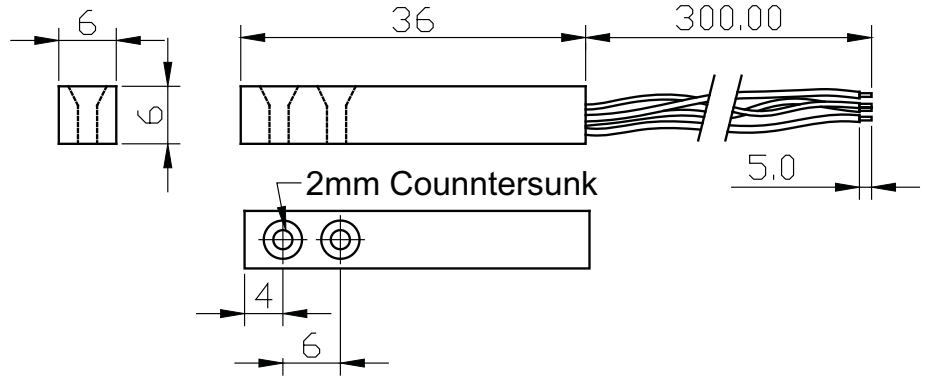

Drawings not to scale
 All dimensions in mm nominal

✓RoHS Compliant

SPECIFICATION

Contact Form / Style		Normally Open
Switching Voltage	Max Volts DC	200
Switching Capacity	Max V/A	10
Switching Current	Max Amps	0.5
Switching Distance	mm	10
Contact Resistance	Max mOhms	500
Operating Temperature	Celsius	- 40° to 125°
Mounting Hole	mm	2.0
Case Material		Aluminium

Applications Include

Options

- Lighting control.
- Alarm switching.
- Control panel.
- Cut off switch.

- two wire version available.
- version available.
- Custom cable types, cable lengths, connectors or crimp terminals available.
- If you do not see what you need, just ask, as there is a strong possibility we can do it !

Did you know we also sell?



Rev. No.

Revision Note

Date

Signature

1

Datasheet

31-07-13

ML



As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : +44 (0)1255 862236

www.comuseurope.co.uk

Fax: +44 (0)1255 862014